

NLS1531**MAS1 Antibody****Unit Size**

0.05 ml

Concentration

1 mg/ml

Storage

Store at 4C short term. Aliquot and store at -20C long term. Avoid freeze-thaw cycles.

Applications

ICC/IF, IHC, IHC-P

Species

Human, Mouse

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.01% Sodium Azide

Immunogen

KLH conjugated synthetic peptide made to the C-terminus of human MAS1. [UniProt# P04201]

Recommended Dilutions

Immunohistochemistry-Paraffin 1:100-1:500, Immunocytochemistry/Immunofluorescence (PMID: 22187625), Immunohistochemistry

Buffer

PBS, [pH7.7]

Uses


This MAS1 antibody is useful for Immunohistochemistry on paraffin-embedded sections and Immunocytochemistry/Immunofluorescence. Prior to immunostaining paraffin tissues, antigen retrieval with sodium citrate buffer (pH 6.0) is recommended.

References

Bosnyak S, Widdop RE, Denton KM, Jones ES. Differential Mechanisms of Ang (1-7)-Mediated Vasodepressor Effect in Adult and Aged Candesartan-Treated Rats. International Journal of Hypertension 2012;2012:1-9. [PMID: 22187625]

Images

Immunohistochemistry: MAS1 Antibody [NLS1531] - IHC analysis of MAS1 in mouse kidney using DAB with hematoxylin counterstain.

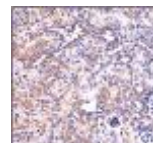

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA
 8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com
Novus Canada
 461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com
Novus Europe
 12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com
