

NBP2-03937**EBI3 Antibody****Unit Size**

0.1 mg

Concentration

Please see the vial label for concentration.

Storage

Store at 4°C short term. Aliquot and store at -20°C long term. Avoid freeze-thaw cycles.

Applications

WB

Species

Human, Mouse

Host

Rabbit

Clonality

Polyclonal

Purity

Protein G purified

Preservative

0.05% Sodium Azide

Immunogen

A portion of amino acids 50-100 of human EBI3 was used as the immunogen.

Recommended Dilutions

Western Blot 2-6ug/ml

Buffer


100 ug in 200 ul PBS containing 0.05% BSA

Uses

This product is useful for Western blot analysis

Images

Western Blot: EBI3 Antibody [NBP2-03937] - analysis of EBI3 using IMG-6185A in 1) Daudi cell lysate using 2.0 ug/ml, 2) Ramos cell lysate at 2.0 ug/ml in the absence of immunizing peptide 3) Ramos cell lysate at 2.0 ug/ml in the presence of ... See more at www.novusbio.com/NBP2-03937

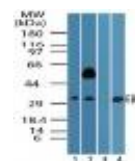

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

