

NBP2-03824**USP9x Antibody (2G7)****Unit Size**

0.1 ml

Concentration

Please see the vial label for concentration.

Storage

Store at 4C short term. Aliquot and store at -20C long term. Avoid freeze-thaw cycles.

Applications

WB, IHC, IHC-P

Species

Human, Mouse, Rat, Canine, Primate

Molecular Weight

292kDa

Host

Mouse

Clonality

Monoclonal

Isotype

IgG2a

Purity

Affinity purified

Preservative

0.02% Sodium Azide

Updated 3/9/2013 2.0

Immunogen

Human recombinant protein fragment corresponding to amino acids 2246-2570 of human USP9X (NP_001034680) produced in E.coli.

Recommended Dilutions


Western Blot 1:500-2000, Immunohistochemistry-Paraffin 1:150, Immunohistochemistry

Buffer

PBS (PH 7.3) containing 1% BSA, 50% glycerol

Images (more available at www.novusbio.com/NBP2-03824)

Western Blot: USP9x Antibody (2G7) [NBP2-03824]
 Analysis of extracts (35ug) from 9 different cell lines by using anti-USP9x monoclonal antibody (HepG2: human; HeLa: human; SVT2: mouse; A549: human; COS7: monkey; Jurkat: human; MDCK: canine;...
 See more at www.novusbio.com/NBP2-03824

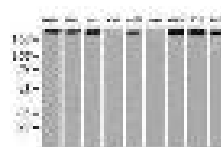

Immunohistochemistry-Paraffin: USP9x Antibody (2G7) [NBP2-03824] - Staining of paraffin-embedded Human prostate tissue using anti-USP9x mouse monoclonal antibody.



Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

