

NBP1-78065**UBE2J1 Antibody****Unit Size**

0.1 mg

Concentration

0.71 mg/ml

Storage

Store at 4°C short term. Aliquot and store at -20°C long term. Avoid freeze-thaw cycles.

Applications

WB, ELISA, IP

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.01% Sodium Azide

Immunogen

This affinity purified antibody was prepared from whole rabbit serum produced by repeated immunizations with a synthetic peptide corresponding to residues near the amino terminus of the human Ube2j1 protein (NP_057105).

Recommended Dilutions

ELISA 1:1000 - 1:5000, Immunoprecipitation 1-2 ug, Western Blot 1:200 - 1:2000

Buffer


0.02 M Potassium Phosphate, 0.15 M Sodium Chloride, pH 7.2

Uses

This affinity purified antibody has been tested for use in ELISA, western blotting and immunoprecipitation. Expect a band approximately 35-40 kDa in size corresponding - ube2j1 protein by western blotting in the appropriate cell lysate or extract.

Images

Western Blot: UBE2J1 Antibody [NBP1-78065] - Shows detection of Ube2j1 in 293 cells over-expressing Myc-Ube2j1 (Lane 2). Lane 1 contains lysate from mock-transfected 293 cells. Personal Communication, A. Weissman and T. Shang, CCR-NCI, Frede... See more at www.novusbio.com/NBP1-78065

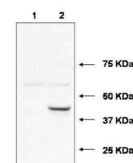

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

