

NBP1-78162**VLDL Receptor Antibody (6A6)****Unit Size**

0.1 ml

Concentration

1 mg/ml

Storage

Store at 4°C short term. Aliquot and store at -20°C long term. Avoid freeze-thaw cycles.

Applications

WB, ICC/IF, IHC, IHC-P

Species

Human, Mouse, Rat, Bovine

Host

Mouse

Clonality

Monoclonal

Isotype

IgG1

Purity

Protein G purified

Preservative

0.05% Sodium Azide

Immunogen

Synthetic peptide corresponding to the C-terminus of human VLDL Receptor [Swiss-Prot# P98155]

Recommended Dilutions

Immunocytochemistry/Immunofluorescence 1:50, Immunohistochemistry, Immunohistochemistry-Paraffin 1:200, Western Blot 1:1000

Buffer

Tris-glycine, 150 mM NaCl

Uses


This VLDL Receptor (6A6) antibody is useful for Immunocytochemistry/Immunofluorescence, Immunohistochemistry on paraffin-embedded sections and Western blot, where various isoforms can be detected between 120 and 168 kDa (see reference Jokinen et al, 1994).

References (more available at www.novusbio.com/NBP1-78162)


Jokinen EV, Landschulz KT, Wyne KL, Ho YK, Frykman PK, Hobbs HH. Regulation of the very low density lipoprotein receptor by thyroid hormone in rat skeletal muscle. . J Biol Chem. ;269(42):26411-8. . 1994 Oct 21. [PMID: 7929362] (WB, Rat

Images (more available at www.novusbio.com/NBP1-78162)

Western Blot: VLDL Receptor Antibody (6A6) [NBP1-78162] - Analysis of VLDL Receptor expression in mouse kidney.

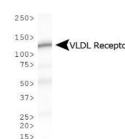

Immunocytochemistry/Immunofluorescence: VLDL Receptor Antibody (6A6) [NBP1-78162] - VLDL Receptor antibody was tested in HeLa cells with FITC (green). Nuclei and actin were counterstained with Dapi (blue) and Phalloidin (red).

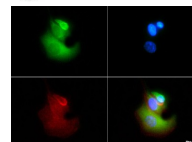

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA
 8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com
Novus Canada
 461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com
Novus Europe
 12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com
