

NBP1-77144**TMEM34 Antibody****Unit Size**

0.1 mg

Concentration

1 mg/ml

Storage

Store at 4C short term. Aliquot and store at -20C long term. Avoid freeze-thaw cycles.

Applications

WB, ELISA, IHC, IHC-P

Species

Human, Mouse, Rat

Host

Rabbit

Clonality

Polyclonal

Purity

Affinity purified

Preservative

0.02% Sodium Azide

Immunogen

Antibody was raised against a 15 amino acid peptide near the carboxy terminus of human TMEM184C

Recommended Dilutions

ELISA, Western Blot, Immunohistochemistry-Paraffin, Immunohistochemistry

Buffer

 
PBS containing 0.02% sodium azide.

Uses


ELISA, Western Blot, Immunohistochemistry-Paraffin

Images

Western Blot: TMEM34 Antibody [NBP1-77144] - Analysis of TMEM184C in mouse heart tissue lysate with TMEM184C antibody at 1 ug/mL.



Immunohistochemistry-Paraffin: TMEM34 Antibody [NBP1-77144] - Mouse heart tissue with TMEM184C antibody at 5 ug/mL.

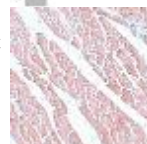

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

