

NBP1-49969**SMCHD1 Antibody****Unit Size**

0.1 ml

Concentration

0.2 mg/ml

Storage

Store at 4C. Do not freeze.

Applications

WB, IP

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen for this product maps to a region between residue 1955 and 2005 of human Structural Maintenance of Chromosomes Flexible Hinge Domain containing 1, using the numbering given in entry NP_056110.2 (GeneID 23347).

Recommended Dilutions

Immunoprecipitation 2 -5 ug/mg lysate, Western Blot 1:2000 -1:10000

Buffer


Tris-buffered Saline and 0.1% BSA

Uses

This antibody works in Western Blot 1:2000 - 1:10000, 2 - 5 mcg/mg.

Images

Western Blot: SMCHD1 Antibody [NBP1-49969] - Detection of Human SmcHD1 by Western Blot and Immunoprecipitation. Samples: Whole cell lysate from HeLa (5, 15 and 50 mcg for WB; 1 mg for IP, 20% of IP loaded) and 293T (T; 50 mcg) cells. Anti... See more at www.novusbio.com/NBP1-49969

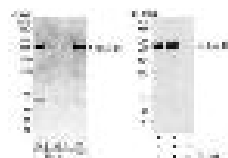

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

