

NBP1-51524**Bcl10 Antibody (4F8)****Unit Size**

0.1 mg

Concentration

Please see the vial label for concentration.

Storage

Store at 4C short term. Aliquot and store at -20C long term. Avoid freeze-thaw cycles.

Applications

WB, ELISA, FLOW, ICC/IF, IHC, IHC-P

Species

Human, Mouse

Host

Mouse

Clonality

Monoclonal

Isotype

IgG1

Purity

Affinity purified

Preservative

0.03% Sodium Azide

Immunogen

Purified recombinant fragment of human BCL-10 expressed in E. Coli.

Recommended Dilutions

Immunohistochemistry-Paraffin 1:200 - 1:1000, Western Blot 1:500 - 1:2000, ELISA 1:10000, Flow Cytometry 1:200 - 1:400, Immunocytochemistry/Immunofluorescence 1:200 - 1:1000, Immunohistochemistry

Buffer

Purified antibody in PBS containing 0.03% sodium azide.

Uses

 
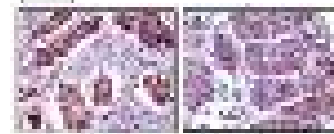
This antibody is useful in Western Blot, ELISA, Immunohistochemistry-p, Immunofluorescence, Flow Cytometry.

References

Bhattacharyya S, Pant N, Dudeja PK, Tobacman JK. Development, evaluation, and application of a highly sensitive microtiter plate ELISA for human Bcl10 protein. J Immunoassay Immunochem 2007 [PMID: 17613665] (ELISA, Human)

Images (more available at www.novusbio.com/NBP1-51524)

Western Blot: Bcl10 Antibody (4F8) [NBP1-51524] - Western blot analysis using BCL10 mouse mAb against NIH/3T3 (1), Hela (2), MCF-7 (3) and Jurkat (4) cell lysate.

Immunohistochemistry-Paraffin: Bcl10 Antibody (4F8) [NBP1-51524] - Immunohistochemical analysis of paraffin-embedded human breast carcinoma (A) and liver carcinoma (B), showing cytoplasmic localization using BCL10 mouse mAb with DAB stainin... See more at www.novusbio.com/NBP1-51524

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA
 8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com
Novus Canada
 461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com
Novus Europe
 12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com
