

**NBP1-49707****SUGT1 Antibody****Unit Size**

0.1 mg

**Concentration**

1 mg/ml

**Storage**

Store at 4C. Do not freeze.

**Applications**

WB, IP

**Species**

Human, Mouse

**Host**

Rabbit

**Clonality**

Polyclonal

**Purity**

Immunogen affinity purified

**Preservative**

0.09% Sodium Azide

**Immunogen**

The immunogen for this product maps to a region between residue 315 and 365 of human Suppressor of G2 Allele of SKP1 using the numbering given in entry NP\_001124384.1 (GeneID 10910).

**Recommended Dilutions**

Immunoprecipitation 2 -5 ug/mg lysate, Western Blot 1:2000 -1:10000

**Buffer**


Tris-citrate/phosphate buffer, pH 7 to 8

**Uses**

This product is useful in Western Blot, Immunoprecipitation.

**Images**

Western Blot: SUGT1 Antibody [NBP1-49707] - Detection of Human and Mouse Sgt1 (SUGT) by Western Blot (h&m) and Immunoprecipitation (h). Samples: Whole cell lysate from HeLa (5, 15 and 50 mcg for WB; 1 mg for IP, 20% of IP loaded), 293T (T; ... See more at [www.novusbio.com/NBP1-49707](http://www.novusbio.com/NBP1-49707)

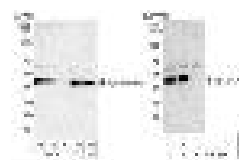

Updated 3/9/2013 2.0

**Limitations:** This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit [www.novusbio.com/guarantee](http://www.novusbio.com/guarantee).**

**Novus USA**

8100 Southpark Way, A-8  
 Littleton, CO 80120  
 p) 888-506-6887  
 p) 303-730-1950  
 f) 303-730-1966  
[novus@novusbio.com](mailto:novus@novusbio.com)

**Novus Canada**

461 North Service Road West,  
 Unit B37  
 Oakville, ON L6M 2V5  
 p) 855-668-8722  
 f) 905-827-6402  
[canada@novusbio.com](mailto:canada@novusbio.com)

**Novus Europe**

12 Cambridge Science Park  
 Cambridge, UK CB4 0FQ  
 UK: p) +44-1223-426-001, f) +44-871-971-1635  
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79  
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340  
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31  
[europe@novusbio.com](mailto:europe@novusbio.com)

