

NBP1-44238**SLC1A4 Antibody****Unit Size**

0.05 ml

Concentration

Concentrations vary lot to lot. See vial label for concentration.

Storage

Store at 4C short term. Aliquot and store at -80C long term. Avoid freeze-thaw cycles.

Applications

IHC, IHC-P

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Peptide affinity purified

Preservative

0.1% Sodium Azide

Specificity/Sensitivity

This product is specific for Slc1a4. Unless other species reactivities are specified there is no testing data currently available.

Immunogen

The immunogen for this antibody is Slc1a4 taken from the source. The exact immunogenic sequence is proprietary.

Recommended Dilutions

Immunohistochemistry, Immunohistochemistry-Paraffin

Buffer


Phosphate buffered saline, PH 7.7

Uses

This product is useful for Immunohistochemistry-Paraffin

Images

Immunohistochemistry-Paraffin: SLC1A4 Antibody [NBP1-44238] - Human, Testis: Formalin-Fixed Paraffin-Embedded (FFPE)

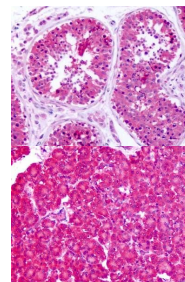

Immunohistochemistry-Paraffin: SLC1A4 Antibody [NBP1-44238] - Human, Pancreas: Formalin-Fixed Paraffin-Embedded (FFPE)

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

