

**NBP1-30472****STAG2 Antibody****Unit Size**

0.1 ml

**Concentration**

0.2 mg/ml

**Storage**

Store at 4°C. Do not freeze.

**Applications**

WB, IP

**Species**

Human

**Molecular Weight**

141kDa

**Host**

Rabbit

**Clonality**

Polyclonal

**Purity**

Immunogen affinity purified

**Preservative**

0.09% Sodium Azide

**Immunogen**

The immunogen for this product maps to a region between residue 1 and 50 of human stromal antigen 2 using the numbering given in entry NP\_006594.3 (GeneID 10735).

**Recommended Dilutions**


Immunoprecipitation 2 -5 ug/mg lysate, Western Blot 1:2000 -1:10000

**Buffer**

Tris-buffered Saline and 0.1% BSA

**Images**

Western Blot: STAG2 Antibody [NBP1-30472] - Western Blot and Immunoprecipitation: Whole cell lysate from HeLa and 293T cells. SA2 was also immunoprecipitated by rabbit anti-SA2 antibody NBP1-30473.

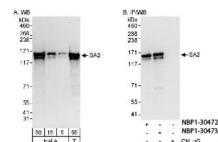

Updated 3/9/2013 2.0

**Limitations:** This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit [www.novusbio.com/guarantee](http://www.novusbio.com/guarantee).**

**Novus USA**

8100 Southpark Way, A-8  
 Littleton, CO 80120  
 p) 888-506-6887  
 p) 303-730-1950  
 f) 303-730-1966  
[novus@novusbio.com](mailto:novus@novusbio.com)

**Novus Canada**

461 North Service Road West,  
 Unit B37  
 Oakville, ON L6M 2V5  
 p) 855-668-8722  
 f) 905-827-6402  
[canada@novusbio.com](mailto:canada@novusbio.com)

**Novus Europe**

12 Cambridge Science Park  
 Cambridge, UK CB4 0FQ  
 UK: p) +44-1223-426-001, f) +44-871-971-1635  
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79  
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340  
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31  
[europe@novusbio.com](mailto:europe@novusbio.com)

