

NBP1-31287**Bak Antibody****Unit Size**

0.1 mg

Concentration

Concentrations vary lot to lot. See vial label for concentration.

Storage

Store at -20C. Avoid freeze-thaw cycles.

Applications

WB, ELISA, IHC-P

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Affinity purified

Preservative

0.01% Thimerosal

Immunogen

Synthetic peptide corresponding to a region within amino acids 1 and 44 of BAK1 (Uniprot ID#Q16611)

Recommended Dilutions

ELISA, Immunohistochemistry-Paraffin, Western Blot 1:500-1:3000

Buffer

 
0.1M Tris, 0.1M Glycine, 10% Glycerol (pH7.0).

Uses


ELISA, Western blot. The usefulness of this product in other applications has not been determined.

Images

Western Blot: Bak Antibody [NBP1-31287] - Sample (30 ug of whole cell lysate) A: HeLa B: Hep G2 C: Molt-4 12% SDS PAGE; antibody diluted at 1:1000.



Immunohistochemistry-Paraffin: Bak Antibody [NBP1-31287] - Paraffin-embedded Liver, bile duct, using antibody 10 ug/ml.

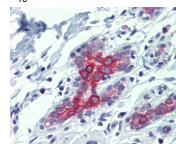

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

