

NB500-201H**Survivin Antibody [HRP]****Unit Size**

0.05 ml

Concentration

1.0 mg/ml

Storage

Store at 4°C in the dark.

Applications

WB, ICC/IF, IHC, IHC-P, IP

Species

Human, Mouse, Rat, Canine, Feline

Host

Rabbit

Clonality

Polyclonal

Conjugate

HRP

Purity

Affinity purified

Preservative

No Preservative

Marker

Astrocyte Marker

Specificity/Sensitivity

This is specific for survivin.

Immunogen

Full-length recombinant human survivin.

Recommended Dilutions

Immunocytochemistry/Immunofluorescence, Immunohistochemistry, Immunohistochemistry-Paraffin 0.5 µg/ml, Immunoprecipitation, Western Blot 1 µg/ml

Buffer

 
PBS

Uses


By Western blot, this antibody recognizes a band at ~16.5 kDa representing survivin. Immunohistochemistry with cytoplasmic and nuclear detection of survivin can be achieved using formalin-fixed paraffin-embedded tissue sections with prior antigen retrieval (pressure cooking).

Images (more available at www.novusbio.com/NB500-201H)

Western Blot: Survivin Antibody [HRP] [NB500-201H] - Detection of survivin in HeLa whole cell lysate (30 µg) using NB 500-201 at 1 µg/ml (1 minute exposure).



Immunocytochemistry/Immunofluorescence: Survivin Antibody [HRP] [NB500-201H] - Telophase with accumulation of survivin in the midbodies of two daughter cells. Survivin detection using NB500-201.

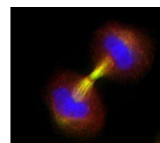

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

