

NB500-512**Vimentin Antibody (VI-RE/1)****Unit Size**

0.1 mg

Concentration

1 mg/ml

Storage

Store at 4C short term. Aliquot and store at -20C long term. Avoid freeze-thaw cycles.

Applications

WB, ELISA, FLOW, ICC/IF

Species

Human, Mouse (Negative), Porcine (Negative)

Host

Mouse

Clonality

Monoclonal

Isotype

IgG1

Purity

Affinity purified

Preservative

15mM Sodium Azide

Marker

Neuronal Stem Cell Marker, Cytoskeleton-Intermediate Filaments Marker

Updated 3/9/2013 2.0

Specificity/Sensitivity

Vimentin - Stem Cell (VI-RE/1)

Immunogen

Recombinant full length protein (Human).

Recommended Dilutions

Flow Cytometry, Western Blot 1:1000, ELISA 1:2000, Immunocytochemistry/Immunofluorescence

Buffer


Constituents: PBS. pH 7.4

Uses

Western Blot detects a band of approximately 57 kDa. This antibody recognizes a different epitope on human vimentin than NB500-316, making them suitable as an ELISA pair.

Images

flow cytometry / FACS analysis: Vimentin Antibody (VI-RE/1) [NB500-512] - Intracellular flow cytometry analysis of Vimentin expression in LEP-19 human fibroblast cell line using anti-human Vimentin (VI-RE/1) PE. Overlay with Isotype mouse I... See more at www.novusbio.com/NB500-512

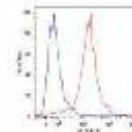

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

