

NB120-15545

Thyroid Hormone Receptor beta Antibody

Unit Size

0.5 ml

Concentration

0.2 mg/ml

Storage

Store at 4C short term. Aliquot and store at -20C long term. Avoid freeze-thaw cycles.

Applications

IHC, IHC-P

Species

Human, Canine

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

Sodium Azide

Specificity/Sensitivity

Thyroid Hormone Receptor beta

Immunogen

Synthetic peptide: GMSEACLHRKSHSERRSTLK, corresponding to amino acids 31-50 of Human Thyroid Hormone Receptor beta.

Recommended Dilutions

Immunohistochemistry-Paraffin 1:100, Immunohistochemistry

Buffer


Constituents: BSA, 10mM PBS. pH 7.4

Uses

Immunohistochemistry-Paraffin Staining of formalin-fixed tissues requires boiling tissue sections in 10mM citrate buffer, pH 6.0 for 10 min followed by cooling at RT for 20 min.

Images

Immunohistochemistry: THR b Antibody [NB120-15545] - Formalin fixed paraffin embedded human colon carcinoma stained with THR b antibody.

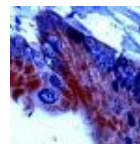

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

