

NB120-3450**Mint 3 Antibody****Unit Size**

0.1 mg

Concentration

Concentrations vary lot to lot. See vial label for concentration.

Storage

Store at -20C. Avoid freeze-thaw cycles.

Applications

WB

Species

Mouse, Rat

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.05% Sodium Azide

Specificity/Sensitivity

NB120-3450 detects munc-18 interacting protein 3 (Mint3) from mouse cells and rat brain samples.

Immunogen

Synthetic peptide: MEFLPEPQHPPGPPTMDLE, corresponding to amino acids 1-19 of Rat Mint3.

Recommended Dilutions

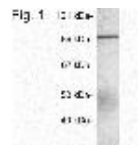
Western Blot

Buffer

PBS

Uses

Western Blot: use at a concentration of 2 ug/ml. Not tested in other applications. Optimal dilutions / concentrations should be determined by the end user. By Western blot, this antibody detects an ~86 kDa protein representing Mint 3 from AtT20 cell extract.

ImagesWestern Blot: Mint 3 Antibody [NB120-3450]
Detection of Mint3 from AtT20 cell extract.

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA
 8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com
Novus Canada
 461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com
Novus Europe
 12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com
