

NB100-82048**MEK3 [p Ser189] Antibody****Unit Size**

0.05 mg

Concentration

1.0 mg/ml

Storage

Aliquot and store at -20C or -80C. Avoid freeze-thaw cycles.

Applications

WB, IHC, IHC-P

Species

Human, Rat

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.02% Sodium Azide

Specificity/Sensitivity

MKK3 (specific to Phospho-Ser189) detects endogenous levels of MKK3 only when phosphorylated at serine189.

Immunogen

The antiserum was produced against synthesized phosphopeptide derived from human MKK3 around the phosphorylation site of serine 189 (V-D-SP-V-A).

Recommended Dilutions

Immunohistochemistry-Paraffin, Western Blot, Immunohistochemistry

Buffer

phosphate buffered saline (without Mg2+ and Ca2+), pH 7.4, 150mM NaCl, and 50% glycerol.


Uses

This antibody is useful for: Western Blot immunohistochemistry-Paraffin

Images

Western Blot: MKK3 Phosphospecific Antibody [NB100-82048] - Western blot analysis of extract from MDA-MB-435 cells untreated or treated with UV, using MKK3 (Ab-189) antibody (Lane 1 and 2) and MKK3 (phospho-Ser189) antibody (Lane 3 and 4).

Immunohistochemistry: MKK3 Phosphospecific Antibody [NB100-82048] - Immunohistochemical analysis of paraffin-embedded human breast carcinoma tissue, using MKK3 (phospho-Ser189) antibody

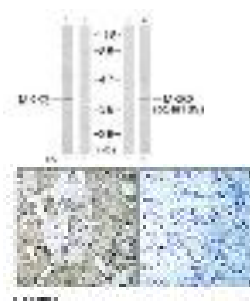

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

