

NB100-2253**Sin3A Antibody****Unit Size**

0.1 ml

Concentration

0.2 mg/ml

Storage

Store at 4C. Do not freeze.

Applications

WB, IP

Species

Human, Mouse

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen recognized by this antibody maps to a region between residue 375 and 425 of human SIN3 homolog A using the numbering given in entry NP_056292.1 (GeneID 25942).

Recommended Dilutions


Immunoprecipitation 2 -5 ug/mg lysate, Western Blot 1:2000 -1:10000

Buffer

Tris-buffered Saline and 0.1% BSA

Images

Western Blot: Sin3A Antibody [NB100-2253] - Detection of Human and Mouse Sin3A on HeLa whole cell lysate using NB100-2253. Sin3A was also immunoprecipitated using rabbit anti-Sin3A antibodies NB100-2252, NB100-2254 and another Sin3A antibody... See more at www.novusbio.com/NB100-2253

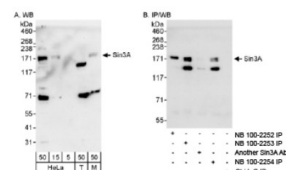

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

