




Syntaxin 5 Antibody [5A6]

CATALOG NUMBER: 51-517

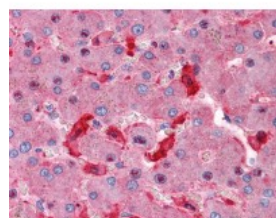

Immunohistochemistry of human liver tissue stained using Syntaxin 5 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	Syntaxin 5 antibody can be used in Western Blot, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	STX5A (NP_003155, 1 a.a. ~ 101 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store Syntaxin 5 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	STX5, SED5, STX5A, Syntaxin 5A, Syntaxin-5, Syntaxin 5
ACCESSION NO.:	Q13190
PROTEIN GI NO.:	114152881
OFFICIAL SYMBOL:	STX5
GENE ID:	6811

Background

