




ARID3A Antibody [1A11]

CATALOG NUMBER: 51-695

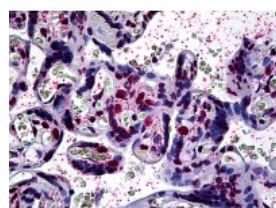

Immunohistochemistry of human placenta tissue stained using ARID3A Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	ARID3A antibody can be used in Western Blot starting at 0.5 - 2 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Recombinant protein
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.4.
STORAGE CONDITIONS:	ARID3A antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	ARID3A, ARID domain-containing 3A, BRIGHT, Dead ringer-like protein 1, Dead ringer-like 1, DRX, E2FBP1, E2F-binding protein 1, DRIL1, DRIL3
ACCESSION NO.:	Q99856
PROTEIN GI NO.:	12230034
OFFICIAL SYMBOL:	ARID3A
GENE ID:	1820

