




Galectin 4 Antibody [1E8]

CATALOG NUMBER: 51-972

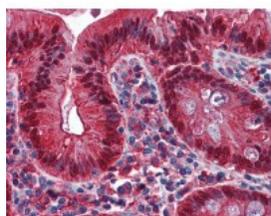

Immunohistochemistry of human colon tissue stained using Galectin 4 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	Galectin 4 antibody can be used in Western Blot starting at 2 ug/mL, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	LGALS4 (NP_006140, 51 a.a. ~ 151 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Aliquot and store Galectin 4 antibody at -20 °C or -80 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2a,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	LGALS4, Antigen NY-CO-27, GAL4, Galectin 4, L36LBP, L-36 lactose-binding protein, Gal-4, Galectin-4, Lactose-binding lectin 4
ACCESSION NO.:	P56470
PROTEIN GI NO.:	3024079
OFFICIAL SYMBOL:	LGALS4
GENE ID:	3960

