




PIP5K2A Antibody [3A3]

CATALOG NUMBER: 51-980

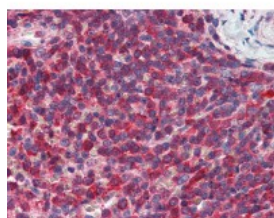

Immunohistochemistry of human spleen tissue stained using PIP5K2A Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	Pimmunoprecipitation5K2A antibody can be used in Western Blot starting at 1 ug/mL, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	PIP5K2A (NP_005019, 304 a.a. ~ 366 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store PIP5K2A antibody at -20 °C or lower. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	PIP4K2A, PI(5)P 4-kinase type II alpha, PIP5KII-alpha, PIP5KIII, PIPK, PtdIns(4)P-5-kinase B isoform, PtdIns(4)P-5-kinase C isoform, PI5P4KA, PIP4KII-alpha, PIP5K2, PIP5KIIalpha, PIP5K2A, PIP5KIIA
ACCESSION NO.:	P48426
PROTEIN GI NO.:	18266879
OFFICIAL SYMBOL:	PIP4K2A
GENE ID:	5305

