




ZNF654 Antibody [NKI/C3]

CATALOG NUMBER: 51-996

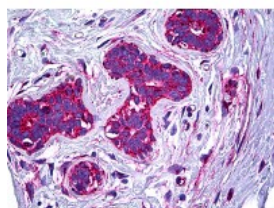

Immunohistochemistry of human breast tissue stained using ZNF654 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	IHC
APPLICATIONS:	ZNF654 antibody can be used in ELISA, Western Blot starting at 1:250 - 1:1000, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Ascites
PHYSICAL STATE:	Liquid
BUFFER:	Ascites, 50 mM PBS at, pH 7.4, 1% BSA, 15 mM sodium azide
STORAGE CONDITIONS:	ZNF654 antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	zfp654
ACCESSION NO.:	ZNF654
PROTEIN GI NO.:	170284741
OFFICIAL SYMBOL:	znf654
GENE ID:	779560

Background

FOR RESEARCH USE ONLY

