




Chromogranin A Antibody [LK2H10]

CATALOG NUMBER: 70-004

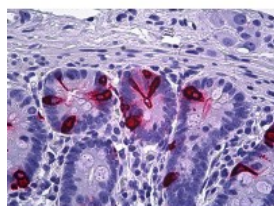

Immunohistochemistry of human Intestine
tissue stained using Chromogranin A
Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	IHC, WB
APPLICATIONS:	Chromogranin A antibody can be used in ELISA, Western Blot, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Ascites
PHYSICAL STATE:	Liquid
BUFFER:	Tris/HCl buffer, 0.09% sodium azide
STORAGE CONDITIONS:	Chromogranin A antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	CHGA, Chromogranin A, Chromogranin-A, Pancreastatin, Pituitary secretory protein I, Vasostatin I, SP-I, Vasostatin II
ACCESSION NO.:	P10645
PROTEIN GI NO.:	215274270
OFFICIAL SYMBOL:	CHGA
GENE ID:	1113

Background

FOR RESEARCH USE ONLY

