




ROCK2 Antibody [1E12]

CATALOG NUMBER: 51-544

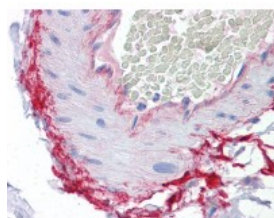

Immunohistochemistry of human vessel tissue stained using ROCK2 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	ROCK2 antibody can be used in Western Blot, immunohistochemistry starting at 5 ug/mL, and immunocytochemistry.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	ROCK2 (NP_004841, 1279 a.a. ~ 1389 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store ROCK2 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	ROCK2, KIAA0619, p164 ROCK-2, Rho kinase 2, RhoA-associated kinase-2, ROCK-II, Rho kinase II, Rok beta, Rok2, RockII
ACCESSION NO.:	O75116
PROTEIN GI NO.:	269849761
OFFICIAL SYMBOL:	ROCK2
GENE ID:	9475

FOR RESEARCH USE ONLY

December 13, 2016