




YAP1 Antibody [2H1]

CATALOG NUMBER: 51-553

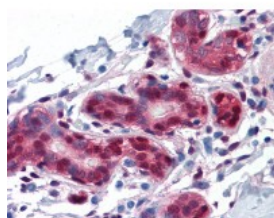

Immunohistochemistry of human breast tissue stained using YAP1 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IF, IHC, WB
APPLICATIONS:	YAP1 antibody can be used in Western Blot, and immunohistochemistry starting at 5 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	YAP1 (NP_006097, 53 a.a. ~ 162 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Store YAP1 antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG2a,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	YAP1, 65 kDa Yes-associated protein, YAP, Yes-associated protein beta, Yes-associated protein delta, Yorkie homolog, YAP2, Yes-associated protein 1, Yes-associated protein 2, YKI, YAP65
ACCESSION NO.:	P46937
PROTEIN GI NO.:	294862479
OFFICIAL SYMBOL:	YAP1
GENE ID:	10413

Background

