




## TP53RK Antibody [4B9-1H3]

CATALOG NUMBER: 51-600

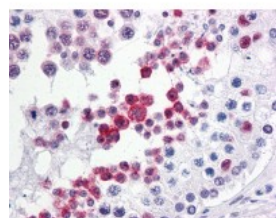

Immunohistochemistry of human testis tissue stained using TP53RK Monoclonal Antibody.

### Specifications

<b>SPECIES REACTIVITY:</b>	Human
<b>TESTED APPLICATIONS:</b>	ELISA, IHC, WB
<b>APPLICATIONS:</b>	TP53RK antibody can be used in immunohistochemistry starting at 1:50, and immunofluorescence.
<b>USER NOTE:</b>	Optimal dilutions for each application to be determined by the researcher.
<b>IMMUNOGEN:</b>	TP53RK (AAH09727, 1 a.a. ~ 254 a.a) full length recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
<b>HOST SPECIES:</b>	Mouse

### Properties

<b>PURIFICATION:</b>	Protein A Column
<b>PHYSICAL STATE:</b>	Liquid
<b>BUFFER:</b>	PBS, pH 7.2
<b>STORAGE CONDITIONS:</b>	Store TP53RK antibody at -20 °C. Aliquot to avoid freeze/thaw cycles.
<b>CLONALITY:</b>	Monoclonal
<b>ISOTYPE:</b>	IgG1,k
<b>CONJUGATE:</b>	Unconjugated

### Additional Info

<b>ALTERNATE NAMES:</b>	TP53RK, C20orf64, BUD32, DJ101A2.2, DJ101A2, Nori-2p, p53-related protein kinase, PRPK, TP53-regulating kinase, Nori-2, TP53 regulating kinase
<b>ACCESSION NO.:</b>	Q96S44
<b>PROTEIN GI NO.:</b>	26398348
<b>OFFICIAL SYMBOL:</b>	TP53RK
<b>GENE ID:</b>	112858

### Background

