




IRAK2 Antibody [6C7]

CATALOG NUMBER: 51-964

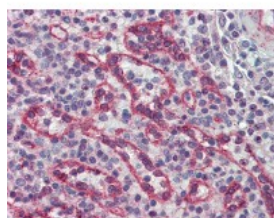

Immunohistochemistry of human spleen tissue stained using IRAK2 Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	IRAK2 antibody can be used in Western Blot starting at 5 ug/mL, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	IRAK2 (NP_001561, 111 a.a. ~ 210 a.a) partial recombinant protein with GST tag. MW of the GST tag alone is 26 KDa.
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Protein A Column
PHYSICAL STATE:	Liquid
BUFFER:	PBS, pH 7.2
STORAGE CONDITIONS:	Aliquot and store IRAK2 antibody at -20 °C or -80 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1,k
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	IRAK2, Il1rak2, IRAK-2
ACCESSION NO.:	O43187
PROTEIN GI NO.:	125987833
OFFICIAL SYMBOL:	IRAK2
GENE ID:	3656

Background

