




WNT8A Antibody

CATALOG NUMBER: 48-357

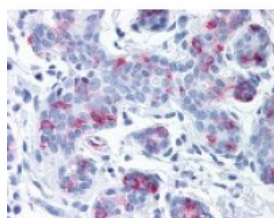

Immunohistochemistry staining of WNT8A
in breast tissue using WNT8A Antibody.

Specifications

SPECIES REACTIVITY:	Bat, Gibbon, Gorilla, Horse, Human, Monkey
TESTED APPLICATIONS:	IHC
APPLICATIONS:	WNT8A antibody can be used in immunohistochemistry starting at 10 ug/mL, and immunofluorescence.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
SPECIFICITY:	BLAST analysis of the peptide immunogen showed no homology with other human proteins.
IMMUNOGEN:	WNT8A antibody was raised against a peptide located near the internal domain of WNT8A (Human).
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Immunoaffinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	PBS, 0.1% sodium azide.
STORAGE CONDITIONS:	WNT8A antibody should be stored long term (months) at -80 °C and short term (days) at 4 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	WNT8A, Protein Wnt-8d, WNT8D, Protein Wnt-8a
ACCESSION NO.:	Q9H1J5
PROTEIN GI NO.:	288558833
OFFICIAL SYMBOL:	WNT8A
GENE ID:	7478

Background

FOR RESEARCH USE ONLY

