


LIPJ Antibody (Center)

Peptide Affinity Purified Rabbit Polyclonal Antibody (Pab)

Catalog #	Applications:	Reactivity:	Accessions:
AP12367c	WB, E	H	Q5W064 , NP_001010939.2
Concentration:	Size:	Isotype:	Clone Name:
0.25 mg/ml	0.1 mg	Rabbit Ig	RB31239

Application Data:

Calculated MW: 42374 Da

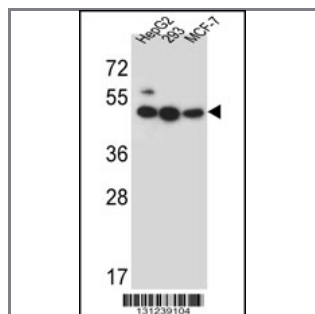

LIPJ Antibody (Center) (Cat. #AP12367c) western blot analysis in HepG2, 293, MCF-7 cell line lysates (35ug/lane). This demonstrates the LIPJ antibody detected the LIPJ protein (arrow).

Gene ID:	Gene Symbol:
142910	LIPJ

Other Names:

LIPJ;Lipase member J;LIPL1

Target/Specificity:

This LIPJ antibody is generated from rabbits immunized with a KLH conjugated synthetic peptide between 193-223 amino acids from the Central region of human LIPJ.

Application Notes:

The suggested dilution is:

ELISA 1:1,000

Western blotting 1:100~500

Format:

Purified polyclonal antibody supplied in PBS with 0.09% (W/V) sodium azide. This antibody is purified through a protein A column, followed by peptide affinity purification.

Storage:

LIPJ Antibody (Center) can be refrigerated at 2-8°C for up to 6 months. For long term storage, place the at -20°C.

Precautions:

LIPJ Antibody (Center) is for research use only and not for use in diagnostic or therapeutic procedures.
