


PITRM1 Antibody (Center)

Peptide Affinity Purified Rabbit Polyclonal Antibody (Pab)

Catalog #	Applications:	Reactivity:	Accessions:
AP12390c	WB, E	H	NP_055704.2 , Q5JRX3
Concentration:	Size:	Isotype:	Clone Name:
0.25 mg/ml	0.1 mg	Rabbit Ig	RB31351

Application Data:

Calculated MW: 117455 Da

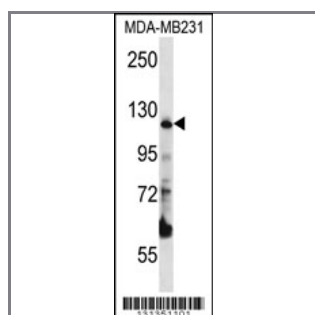

PITRM1 Antibody (Center) (Cat. #AP12390c) western blot analysis in MDA-MB231 cell line lysates (35ug/lane). This demonstrates the PITRM1 antibody detected the PITRM1 protein (arrow).

Gene ID:	Gene Symbol:
10531	PITRM1

Other Names:

PITRM1; Presequence protease, mitochondrial; KIAA1104; MP1

Target/Specificity:

This PITRM1 antibody is generated from rabbits immunized with a KLH conjugated synthetic peptide between 497-526 amino acids from the Central region of human PITRM1.

Application Notes:

The suggested dilution is:
 ELISA 1:1,000
 Western blotting 1:100~500

Format:

Purified polyclonal antibody supplied in PBS with 0.09% (W/V) sodium azide. This antibody is purified through a protein A column, followed by peptide affinity purification.

Storage:

PITRM1 Antibody (Center) can be refrigerated at 2-8°C for up to 6 months. For long term storage,

place the at -20°C.

Precautions:

PITRM1 Antibody (Center) is for research use only and not for use in diagnostic or therapeutic procedures.
