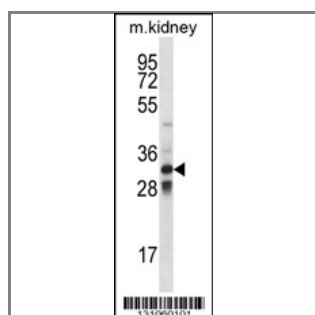


TLX1 Antibody (Center)

Peptide Affinity Purified Rabbit Polyclonal Antibody (Pab)

Catalog #	Applications:	Reactivity:	Accessions:
AP12489c	WB, E	H(predict), M	NP_005512.1 , P31314
Concentration:	Size:	Isotype:	Clone Name:
0.25 mg/ml	0.1 mg	Rabbit Ig	RB31060

Application Data:
Calculated MW: 34365 Da


TLX1 Antibody (Center) (Cat. #AP12489c) western blot analysis in mouse kidney tissue lysates (35ug/lane). This demonstrates the TLX1 antibody detected the TLX1 protein (arrow).

Gene ID:	Gene Symbol:
3195	TLX1

Other Names:

T-cell leukemia homeobox protein 1; TLX1; HOX11; TCL3

Target/Specificity:

This TLX1 antibody is generated from rabbits immunized with a KLH conjugated synthetic peptide between 162-191 amino acids from the Central region of human TLX1.

Application Notes:

The suggested dilution is:

ELISA 1:1,000

Western blotting 1:100~500

Format:

Purified polyclonal antibody supplied in PBS with 0.09% (W/V) sodium azide. This antibody is purified through a protein A column, followed by peptide affinity purification.

Storage:

TLX1 Antibody (Center) can be refrigerated at 2-8°C for up to 6 months. For long term storage,

place the at -20°C.

Precautions:

TLX1 Antibody (Center) is for research use only and not for use in diagnostic or therapeutic procedures.
