


Mouse Flt3 Antibody (N-term)

Peptide Affinity Purified Rabbit Polyclonal Antibody (Pab)

Catalog #	Applications:	Reactivity:	Accessions:
AP14621a	WB, E	M	NP_034359.2 , Q00342
Concentration:	Size:	Isotype:	Clone Name:
0.25 mg/ml	0.1 mg	Rabbit Ig	RB34777

Application Data:

Calculated MW: 112640 Da

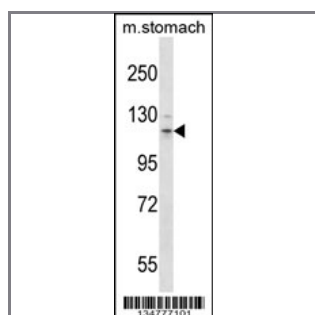

Mouse Flt3 Antibody (N-term) (Cat. #AP14621a) western blot analysis in mouse stomach tissue lysates (35ug/lane). This demonstrates the Flt3 antibody detected the Flt3 protein (arrow).

Gene ID:	Gene Symbol:
14255	Flt3

Other Names:

FL cytokine receptor; Flt3; Flk-2; Flt-3

Target/Specificity:

This Mouse Flt3 antibody is generated from rabbits immunized with a KLH conjugated synthetic peptide between 153-181 amino acids from the N-terminal region of Mouse Flt3.

Application Notes:

The suggested dilution is:

ELISA 1:1,000

Western blotting 1:100~500

Format:

Purified polyclonal antibody supplied in PBS with 0.09% (W/V) sodium azide. This antibody is purified through a protein A column, followed by peptide affinity purification.

Storage:

Mouse Flt3 Antibody (N-term) can be refrigerated at 2-8°C for up to 6 months. For long term

storage, place the at -20°C.

Precautions:

Mouse Flt3 Antibody (N-term) is for research use only and not for use in diagnostic or therapeutic procedures.
