

NLS212**EDG2 Antibody****Unit Size**

0.05 ml

Concentration

Concentrations vary lot to lot. See vial label for concentration.

Storage

Store at 4C short term. Aliquot and store at -80C long term. Avoid freeze-thaw cycles.

Applications

IHC, IHC-P

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.01% Sodium Azide

Specificity/Sensitivity

Lysophosphatidic Acid Receptor Edg2

Immunogen

Synthetic peptide [KLH conjugated] made to the N-term extracellular

Recommended Dilutions

Immunohistochemistry-Paraffin, Immunohistochemistry

Buffer

PBS [pH7.7]

Uses

Immunohistochemistry with formalin fixed paraffin embedded tissues. Not tested for other uses.


References

Horak, CE et al. Nm23-H1 Suppresses Metastasis by Inhibiting Expression of the Lysophosphatidic Acid Receptor EDG2. . Cancer Res 67(24): 11751-11759, . 2007. [PMID: 18089805]

Images

Immunohistochemistry-Paraffin: EDG2 Antibody [NLS212] - Brain, Glia

Adrenal

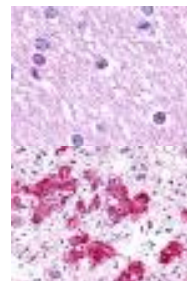

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

