

NBP2-02316**PSMC3 Antibody (9F3)****Unit Size**

0.1 ml

Concentration

Please see the vial label for concentration.

Storage

Store at 4°C short term. Aliquot and store at -20°C long term. Avoid freeze-thaw cycles.

Applications

WB, FLOW, ICC/IF, IHC, IHC-P

Species

Human, Canine

Host

Mouse

Clonality

Monoclonal

Isotype

IgG1

Purity

Affinity purified

Preservative

0.02% Sodium Azide

Immunogen


Full length human recombinant protein of human PSMC3(NP_002795) produced in HEK293T cell.

Recommended Dilutions


Western Blot 1:2000, Immunohistochemistry-Paraffin 1:50, Immunocytochemistry/Immunofluorescence 1:100, Flow Cytometry 1:100, Immunohistochemistry

Buffer

PBS (pH 7.3) containing 1% BSA, 50% glycerol

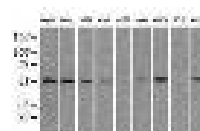Images (more available at www.novusbio.com/NBP2-02316)Western Blot: PSMC3 Antibody (9F3) [NBP2-02316]
Analysis of extracts (35ug) from 9 different cell lines by using anti-PSMC3 monoclonal antibody.

Immunocytochemistry/Immunofluorescence: PSMC3 Antibody (9F3) [NBP2-02316] - Staining of COS7 cells transiently transfected by pCMV6-ENTRY PSMC3.

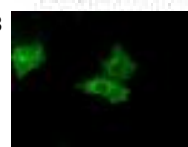

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA
 8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com
Novus Canada
 461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com
Novus Europe
 12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com
