

NBP1-78775**Egr1 Antibody****Unit Size**

0.1 mg

Concentration

1 mg/ml

Storage

Store at 4°C. Do not freeze.

Applications

WB, IP

Species

Human, Mouse

Molecular Weight

56kDa

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen for this product maps to a region between residue 1 and 50 of mouse Early Growth Response Protein 1 using the numbering given in entry NP_031939.1 (GeneID 13653).

Recommended Dilutions


Immunoprecipitation 2 - 10 ug/mg lysate, Western Blot 1:1000 - 1:5000

Buffer

Tris-citrate/phosphate buffer, pH 7 to 8

Images

Western Blot: Egr1 Antibody [NBP1-78775] - Whole cell lysate from mouse bone marrow dendritic (D; 50 and 15 mcg for WB; 1 mg for IP, 20% of IP loaded), NIH3T3 (M; 50 mcg), human erythroleukemia (E; 50 mcg), and Jurkat (J; 50 mcg) cells. Ant... See more at www.novusbio.com/NBP1-78775

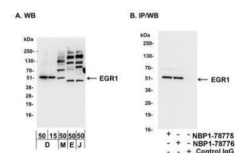

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

