

NBP1-71812**SUV3L1 Antibody****Unit Size**

0.1 mg

Concentration

1 mg/ml

Storage

Store at 4°C. Do not freeze.

Applications

WB, IP

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen for this product maps to a region between residue 686 and 736 of human Suppressor of Var1, 3-like 1 using the numbering given in entry NP_003162.2 (GeneID 6832).

Recommended Dilutions

Immunoprecipitation 2 - 5 mcg/mg, Western Blot

Buffer


Tris-citrate/phosphate buffer, pH 7 to 8

Uses

This antibody works in Immunoprecipitation.

Images

Western Blot: SUV3L1 Antibody [NBP1-71812] - Whole cell lysate (1 mg for IP, 20% of IP loaded) from HeLa cells. Affinity purified rabbit anti-SUV3 antibody used for IP at 6 mcg/mg lysate. SUV3 was also immunoprecipitated by rabbit anti-SU... See more at www.novusbio.com/NBP1-71812

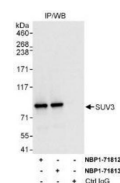

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

