

NBP1-71851**SOX13 Antibody****Unit Size**

0.1 mg

Concentration

1 mg/ml

Storage

Store at 4°C. Do not freeze.

Applications

WB, IP

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen for this product maps to a region between residue 572 and 622 of human Sex Determining Region Y-box 13 using the numbering given in entry NP_005677.2 (GeneID 9580).

Recommended Dilutions

Immunoprecipitation 2 - 10 mcg/mg, Western Blot 1:1000 - 1:5000

Buffer


Tris-citrate/phosphate buffer, pH 7 to 8

Uses

This antibody works in Western Blot, Immunoprecipitation.

Images

Western Blot: SOX13 Antibody [NBP1-71851] - Whole cell lysate from HeLa (5, 15 and 50 mcg for WB; 1 mg for IP, 20% of IP loaded) and 293T (T; 50 mcg) cells. Affinity purified rabbit anti-SOX13 antibody used for WB at 0.4 mcg/ml (A) and 1 m... See more at www.novusbio.com/NBP1-71851

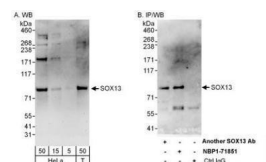

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

