

NBP1-50164**SLC5A4 Antibody****Unit Size**

0.05 ml

Concentration

Concentrations vary lot to lot. See vial label for concentration.

Storage

Store at 4C short term. Aliquot and store at -80C long term. Avoid freeze-thaw cycles.

Applications

IHC, IHC-P

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.1% Sodium Azide

Specificity/Sensitivity

C-terminal domain of human

Immunogen

Synthetic peptide - KLH conjugated

Recommended Dilutions

Immunohistochemistry-Paraffin 20 ug/ml, Immunohistochemistry

Buffer

PBS


Uses

This antibody is useful in Immunohistochemistry-Paraffin .

Images

Immunohistochemistry-Paraffin: SLC5A4 Antibody [NBP1-50164] - Human Liver (formalin-fixed, paraffin-embedded) stained with SLC5A4 antibody at 20 ug/ml followed by biotinylated goat anti-rabbit IgG secondary antibody, alkaline phosphatase-str...

See more at www.novusbio.com/NBP1-50164

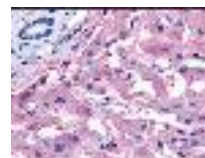

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

