

NBP1-49025**RP105 Antibody (MHR73-11)****Unit Size**

0.1 mg

Concentration

1.0 mg/ml

Storage

Store at 4C. Do not freeze.

Applications

FLOW, IHC, IHC-Fr, IP

Species

Human, Primate

Host

Mouse

Clonality

Monoclonal

Isotype

IgG1 Kappa

Purity

Affinity purified

Preservative

No Preservative

Immunogen

This antibody was generated by immunizing host with Human RP105 complexed with mouse MD-1

Recommended Dilutions

Flow Cytometry, Immunohistochemistry-Frozen, Immunoprecipitation, Immunohistochemistry

Buffer


Phosphate-buffered solution, pH 7.2, containing no preservative.

Uses

For immunofluorescent staining, the suggested use of this reagent is 2.0 ug per million cells in 100 µl volume or 100 µl of whole blood. It is recommended that the reagent be titrated for optimal performance for each application.

Images

Flow Cytometry: RP105 Antibody (MHR73-11) [NBP1-49025] - Human peripheral blood lymphocytes stained with purified MHR73-11, followed by anti-mouse IgG FITC

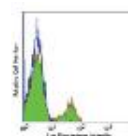

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

