

**NBP1-45327****Bcl2A1 Antibody****Unit Size**

0.1 mg

**Concentration**

0.2 mg/ml

**Storage**

Store at -20C. Avoid freeze-thaw cycles.

**Applications**

WB

**Species**

Human, Mouse, Rat

**Host**

Rabbit

**Clonality**

Polyclonal

**Purity**

Affinity purified

**Preservative**

0.01% Thimerosal

**Immunogen**

Synthetic peptide surrounding amino acid 37 of human A1.

**Recommended Dilutions**

Western Blot

**Buffer**


phosphate-buffered saline (PBS) containing 30% glycerol, 0.5% BSA

**Uses**

Western blotting (0.5-4ug/ml, immunoprecipitation, and immunohistochemistry. However, the optimal conditions should be determined individually. The A1 antibody detects A1 (Bfl-1) of human, mouse, and rat origins.

**Images**

Western Blot: Bcl2A1 Antibody [NBP1-45327] - Western blot analysis of A1 expression with Jurkat cell lysate (Lane 1), mouse small intestine tissue lysate (Lane 2), and rat kidney tissue lysate (Lane 3).

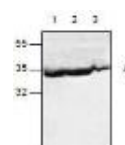

Updated 3/9/2013 2.0

**Limitations:** This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit [www.novusbio.com/guarantee](http://www.novusbio.com/guarantee).**

**Novus USA**

8100 Southpark Way, A-8  
 Littleton, CO 80120  
 p) 888-506-6887  
 p) 303-730-1950  
 f) 303-730-1966  
[novus@novusbio.com](mailto:novus@novusbio.com)

**Novus Canada**

461 North Service Road West,  
 Unit B37  
 Oakville, ON L6M 2V5  
 p) 855-668-8722  
 f) 905-827-6402  
[canada@novusbio.com](mailto:canada@novusbio.com)

**Novus Europe**

12 Cambridge Science Park  
 Cambridge, UK CB4 0FQ  
 UK: p) +44-1223-426-001, f) +44-871-971-1635  
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79  
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340  
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31  
[europe@novusbio.com](mailto:europe@novusbio.com)

