

NBP1-45875

Syndecan 1 Antibody

Unit Size

0.1 mg

Concentration

0.5 mg/ml

Storage

Aliquot and store at -20C or -80C. Avoid freeze-thaw cycles.

Applications

WB

Species

Human, Mouse, Rat

Host

Rabbit

Clonality

Polyclonal

Isotype

IgG

Purity

Affinity purified

Preservative

0.01% Thimerosal

Immunogen

Synthetic peptide surrounding amino acid 298 of human Syndecan-1.

Recommended Dilutions

Western Blot 0.5-4 ug/ml

Buffer


PBS containing 30% glycerol, 0.5% BSA

Uses

The antibody detects ~100 kDa Syndecan-1 from samples of human, mouse, rat, and hamster origins.

Images

Western Blot: Syndecan 1 Antibody [NBP1-45875] - Analysis of Syndecan-1 in 3T3 cell lysate.

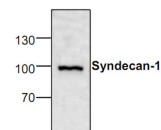

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

