

NBP1-45892**TGF beta 2 Antibody****Unit Size**

0.1 mg

Concentration

0.5 mg/ml

Storage

Store at -20C. Avoid freeze-thaw cycles.

Applications

WB

Species

Human, Mouse, Rat

Host

Rabbit

Clonality

Polyclonal

Purity

Affinity purified

Preservative

0.01% Thimerosal

Immunogen

Synthetic peptide surrounding amino acid 366 of human TGF-beta 2.

Recommended Dilutions

Western Blot 0.5-4 ug/ml

Buffer

PBS, containing 30% glycerol, 0.5% BSA

Uses


The antibody recognizes ~25kDa TGF-beta 2 of human, mouse, and rat origins.

References

Lin J, Teo S, Lam DH, Jeyaseelan K, Wang S MicroRNA-10b pleiotropically regulates invasion, angiogenicity and apoptosis of tumor cells resembling mesenchymal subtype of glioblastoma multiforme Cell Death Dis 2012 Oct 4 [PMID: 23034333] (WB, Human)

Images

Western Blot: TGF beta 2 Antibody [NBP1-45892] - Analysis of TGF-beta 2 using Jurkat cell lysate (Lane 1,2), Mouse 3T3 cell lysate (Lane 3) and Rat kidney tissue lysate (Lane 4).

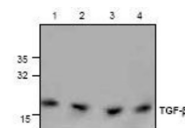

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

