

NBP1-32815**Talin 1 Antibody****Unit Size**

0.1 mg

Concentration

Concentrations vary lot to lot. See vial label for concentration.

Storage

Store at -20C. Avoid freeze-thaw cycles.

Applications

WB, IHC-P

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Affinity purified

Preservative

0.01% Thimerosal

Immunogen

Recombinant fragment corresponding to a region within amino acids 2281 and 2537 of TLN1 (Uniprot ID#Q9Y490)

Recommended Dilutions

Immunohistochemistry-Paraffin, Western Blot 1:500-1:3000

Buffer


0.1M Tris, 0.1M Glycine, 10% Glycerol (pH7.0).

Uses

Western blot. The usefulness of this product in other applications has not been determined.

Images

Western Blot: Talin 1 Antibody [NBP1-32815] - Sample(30 ug of whole cell lysate) A:H1299 5% SDS PAGE, antibody diluted at 1:500.

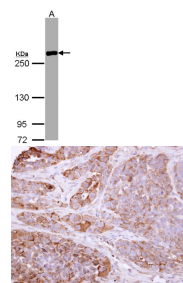

Immunohistochemistry-Paraffin: Talin 1 Antibody [NBP1-32815] - Paraffin-embedded H357 xenograft; antibody dilution 1:500.

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

