

NBP1-30110**STK11IP Antibody****Unit Size**

0.1 ml

Concentration

1.0 mg/ml

Storage

Store at 4C. Do not freeze.

Applications

WB, IP

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

maps to a region between residue 900 and 950 of human serine/threonine kinase 11 interacting protein using the numbering given in entry NP_443134.2

Recommended Dilutions

Immunoprecipitation 2 -5 ug/mg lysate, Western Blot 1:2000 -1:10000

Buffer


Tris-citrate/phosphate buffer, pH 7 to 8

Uses

This antibody is useful in Immunoprecipitation and Western Blot.

Images

Western Blot: STK11IP Antibody [NBP1-30110] - Whole cell lysate from HeLa cells. STK11IP was also immunoprecipitated by rabbit anti-STK11IP antibody NBP1-30109. For blotting IPed STK11IP, the ReliaBLOT® Reagents and Procedures were used.

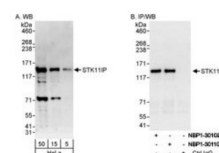

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

