

NBP1-02823**ATRX Antibody (60.1)****Unit Size**

0.05 mg

Concentration

Concentrations vary lot to lot. See vial label for concentration.

Storage

Store at 4°C short term. Aliquot and store at -80°C long term. Avoid freeze-thaw cycles.

Applications

WB, ELISA, IHC, IHC-P

Species

Human

Host

Mouse

Clonality

Monoclonal

Purity

Protein G purified

Preservative

No Preservative

Specificity/Sensitivity

Peptides from N and C termini of RAD54L (ATRX)

Immunogen

Peptides from N and C termini of RAD54L (ATRX)

Recommended Dilutions

ELISA, Immunohistochemistry, Immunohistochemistry-Paraffin 5 ug/ml, Western Blot

Buffer


PBS

Uses

This antibody is useful for the following applications and at the following dilutions: Western Blot, ELISA, Immunohistochemistry-Paraffin 5 ug/ml

Images

Immunohistochemistry-Paraffin: ATRX Antibody (60.1) [NBP1-02823] - Staining of human kidney. Immunohistochemistry of formalin-fixed, paraffin-embedded tissue after heat-induced antigen retrieval. Antibody concentration 5 ug/ml.

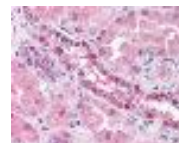

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

