

NBC1-26374

TNFSF9 Protein

Unit Size

0.1 mg

Concentration

1.0 mg/ml

Storage

Store at -80C. Avoid freeze-thaw cycles.

Host

Human

Purity

Protein

Preservative

No Preservative

Immunogen


Sequences of amino acids: MRGSHHHHHH GMASMTGGQQ MGRDLYDDDD
 KDRWGSHMRE GPELSPDDPA GLLDLRQGMF AQLVAQNVLL IDGPLSWYSY
 PGLAGVSLTG GLSYKEDTKE LVVAKAGVYY VFFQLELRV VAGEGSGSVS
 LALHLQPLRS AAGAAALALT VDLPPASSEA RNSAFGFQGR LLHLSAGQRL
 GVHLHTEARA RHAWQLTQGA TVLGLFRVTP EIPAGLPSPR SE

Buffer

20 mM Tris-HCl buffer (pH 8.0) containing 100mM NaCl, 20% glycerol

Images

Western Blot: 4-1BB ligand Protein [NBC1-26374]

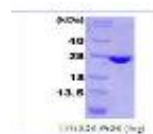

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

