

NB110-60509**OXPAT Antibody****Unit Size**

0.1 ml

Concentration

1.01 mg/ml

Storage

Store at 4C short term. Aliquot and store at -20C long term. Avoid freeze-thaw cycles.

Applications

WB, IHC, IHC-P

Species

Human, Mouse, Bovine, Porcine, Sheep

Molecular Weight

50kDa

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.1% Sodium Azide

Immunogen

A synthetic peptide made to a region of the human OXPAT protein, within residues 300-400. [UniProt# Q00G26]

Recommended Dilutions

Immunohistochemistry 1.0-5.0 ug/ml

Immunohistochemistry-Paraffin 1.0-5.0 ug/ml

Western Blot 0.5 - 2.0 ug/ml

Buffer

 
PBS, 30% glycerol

Uses


This OXPAT antibody is useful for Western blot and Immunohistochemistry on paraffin-embedded sections. In WB a band can be seen at ~50 kDa, representing the OXPAT protein.

Images

Western Blot: OXPAT Antibody [NB110-60509] - Detection of OXPAT in human (lane 1) and mouse (lane 2) heart lysate.



Immunohistochemistry: OXPAT Antibody [NB110-60509] - Staining of OXPAT in paraffin embedded mouse fat.

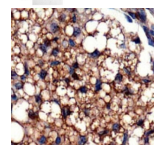

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

