

NB100-93284**EIF2 beta Antibody****Unit Size**

0.1 ml

Concentration

0.2 mg/ml

Storage

Store at 4°C. Do not freeze.

Applications

WB, IHC, IHC-P, IP

Species

Human, Mouse

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen recognized by this antibody maps to a region between residue 283 and 333 of human eukaryotic translation initiation factor 2, subunit 2 beta, 38kDa using the numbering given in entry NP_003899.2 (GeneID 8894).

Recommended Dilutions

Immunohistochemistry, Immunohistochemistry-Paraffin, Immunoprecipitation 2-5 ug/mg lysate, Western Blot 1:2000-1:10000

Buffer

Tris-buffered Saline and 0.1% BSA


Uses

This antibody is useful for Immunohistochemistry-Paraffin, Western Blot and Immunoprecipitation.

Images (more available at www.novusbio.com/NB100-93284)

Western Blot: EIF2 beta Antibody [NB100-93284] - Whole cell lysate from HeLa (5, 15 and 50 mcg for WB; 1 mg for IP, 20% of IP loaded), 293T (T; 50 mcg), and mouse NIH3T3 (M; 50 mcg) cells. NB100-93284 used for WB at 0.04 mcg/ml (A) and 1 mcg... See more at www.novusbio.com/NB100-93284

Immunohistochemistry-Paraffin: EIF2 beta Antibody [NB100-93284] - Human breast carcinoma. Antibody used at a dilution of 1:1,000.

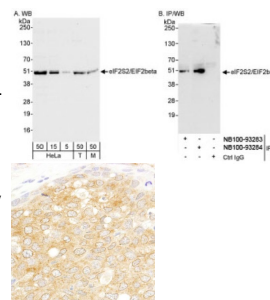

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

