

NB100-93317**eIF4G1 Antibody****Unit Size**

0.1 ml

Concentration

0.2 mg/ml

Storage

Store at 4°C. Do not freeze.

Applications

WB, IHC, IHC-P, IP

Species

Human

Host

Rabbit

Clonality

Polyclonal

Purity

Immunogen affinity purified

Preservative

0.09% Sodium Azide

Immunogen

The immunogen recognized by this antibody maps to a region between residue 525 and 575 of human eukaryotic translation initiation factor 4 gamma, 1 using the numbering given in entry NP_886553.2 (GeneID 1981).

Recommended Dilutions

Immunohistochemistry 1:200

Immunohistochemistry-Paraffin 1:200

Immunoprecipitation 2-5 mcg/mg lysate

Western Blot 1:2000-1:10000

Buffer

Tris-buffered Saline and 0.1% BSA


Uses

This antibody is useful for western blot and immunoprecipitation.

Images

Western Blot: eIF4G1 Antibody [NB100-93317] - Detection of Human eIF4G1 on HeLa whole cell lysate using NB100-93317. eIF4G1 was also immunoprecipitated by rabbit anti-eIF4G1 antibodies NB100-93315 and NB100-93316.

Immunohistochemistry-Paraffin: eIF4G1 Antibody [NB100-93317] - Human ovarian carcinoma. Antibody used at a dilution of 1:200.

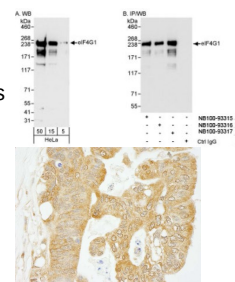

Updated 3/9/2013 2.0

Limitations: This product is for research use only and is not approved for use in humans or in clinical diagnosis. Products are guaranteed for six months from the date of receipt except for peptides and proteins which are guaranteed for 3 months. **For more information on our guarantee, please visit www.novusbio.com/guarantee.**

Novus USA

8100 Southpark Way, A-8
 Littleton, CO 80120
 p) 888-506-6887
 p) 303-730-1950
 f) 303-730-1966
novus@novusbio.com

Novus Canada

461 North Service Road West,
 Unit B37
 Oakville, ON L6M 2V5
 p) 855-668-8722
 f) 905-827-6402
canada@novusbio.com

Novus Europe

12 Cambridge Science Park
 Cambridge, UK CB4 0FQ
 UK: p) +44-1223-426-001, f) +44-871-971-1635
 DE: p) +49-6922-22340-60, f) +49-0800-58926-79
 IT: p) +39-02-4032-6786, f) +39-02-4032-6340
 FR: p) +33-1-76-77-45-30, f) +33-1-76-77-45-31
europe@novusbio.com

